

2 Stage Bevel Ordering Guide



92.1 Bevel



93.1 Bevel



DRIVESYSTEMS

Gear Unit	Shaft/Mounting	Shaft/Mounting Options	Reducer Options	Motor/Input	Motor Options
SK ①	②	③	④	-	⑤

① Gear Unit	
92072.1	93072.1
92172.1	93172.1
92372.1	93372.1
92672.1	93672.1
92772.1	93772.1

② 92.1 Shaft/Mounting	
<input type="checkbox"/> V - Universal Feet/B14 Face Flange/Solid Shaft	<input type="checkbox"/> A - Universal Feet/B14 Face Flange/ Hollow Shaft
<input type="checkbox"/> VF - Universal Feet/B5 Flange/Solid Shaft	<input type="checkbox"/> AF - Universal Feet/B5 Flange/ Hollow Shaft
<input type="checkbox"/> L - Universal Feet/B14 Face Flange/Double Solid Shaft	

② 93.1 Shaft/Mounting	
<input type="checkbox"/> V - B14 Face Flange/Solid Shaft	<input type="checkbox"/> A - B14 Face Flange/Hollow Shaft
<input type="checkbox"/> VF - B5 Flange/ Solid Shaft	<input type="checkbox"/> AF - B5 Flange/Hollow Shaft
<input type="checkbox"/> L - B14 Face Flange/ Double Solid Shaft	<input type="checkbox"/> AX - Tapped Feet/B14 Face Flange/Hollow Shaft
<input type="checkbox"/> VX - Tapped Feet/B14 Face Flange/Solid Shaft	<input type="checkbox"/> AXF - Tapped Feet/B5 Flange/Hollow Shaft
<input type="checkbox"/> VXF - Tapped Feet/B5 Flange/Solid Shaft	
<input type="checkbox"/> LX - Tapped Feet/B14 Face Flange/Double Solid Shaft	

③ Shaft/Mounting Options	
<input type="checkbox"/> Keyed Hollow Shaft	<input type="checkbox"/> D - Torque Arm
<input type="checkbox"/> SH - Shrink Disc & Cover	<input type="checkbox"/> SM -Stainless Steel Shaft
<input type="checkbox"/> MH - GRIPMAXX™	<input type="checkbox"/> SWV -Special Solid Shaft
<input type="checkbox"/> H - Hollow Shaft Cover	<input type="checkbox"/> SWA -Special Hollow Shaft
<input type="checkbox"/> B - Fixing Element Kit	<input type="checkbox"/> Worm Footplate Kit

④ Reducer Options	
<input type="checkbox"/> OSG - Oil Sight Glass	<input type="checkbox"/> LL - Long Term Storage
<input type="checkbox"/> MDP - Magnetic Drain Plug	<input type="checkbox"/> PR - Flange Pilot Removal
<input type="checkbox"/> ADP - Additional Drain Plug	<input type="checkbox"/> VI - Flouro-rubber Seals

⑤ Input Shaft	NEMA Adapter	IEC	Integral Motors	Integral Premium Efficient Motors	Integral Intermittent Duty (60 min) Motors
W	N56C N140TC N180TC N210TC N250TC	IEC 63 IEC 71 IEC 80 IEC 90 IEC 100 IEC 112 IEC 132 IEC 160	63S/4 - 0.16hp 63L/4 - 0.25hp 71S/4 - 0.33hp 71L/4 - 0.50hp 80S/4 - 0.75hp	80LP/4 - 1hp 90SP/4 - 1.5hp 90LP/4 - 2hp 100LP/4 - 3hp 112MP/4 - 5hp 132SP/4 - 7.5hp 132MP/4 - 10hp	80L/4 - 1hp 90S/4 - 1.5hp 90L/4 - 2hp 100L/4 - 3hp 100LA/4 - 5hp 112M/4 - 5.4hp 132S/4 - 7.5hp 132M/4 - 10hp
				Other Speeds Available	Other Speeds Available


Product Specifications

Ratio :1

— OR —

Output Speed rpm

- Mounting Position
- M1
 - M2
 - M3
 - M4
 - M5
 - M6
 - Special _____

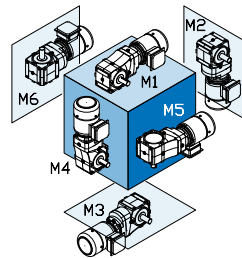

- Paint
- Standard Stainless Steel Paint
 - NSD+ (gray)
 - NSD+W (white)
 - NSD-X3 (gray)
 - NSD-X3W (white)
 - NSD-Tuph
 - Special _____


- Lubricant
- Standard
 - Synthetic
 - Food Grade
 - Other _____

<p>Solid Shaft Side (if required)</p> <ul style="list-style-type: none"> <input type="radio"/> Shaft Side A <input type="radio"/> Shaft Side B <input type="radio"/> Shaft Side A&B 	<p>Hollow Shaft Diameter (if required)</p> <input type="text"/>	<p>B5 Flange Side (if required)</p> <ul style="list-style-type: none"> <input type="radio"/> Flange Side A <input type="radio"/> Flange Side B <input type="radio"/> Flange Side A&B 	<p>B5 Flange Diameter (if required)</p> <input type="text"/>	<p>Torque Arm Side & Location (if required)</p> <ul style="list-style-type: none"> <input type="radio"/> Side A <input type="text"/> <input type="radio"/> Side B <input type="text"/> <p style="text-align: center;">Location</p>	<p>Shrink Disc /GRIPMAXX™ Side (if required)</p> <ul style="list-style-type: none"> <input type="radio"/> Side A <input type="radio"/> Side B 	<p>H66 Side (if required)</p> <ul style="list-style-type: none"> <input type="radio"/> H66 Side A <input type="radio"/> H66 Side B
---	--	--	---	---	--	---

Gearmotor Only Details


- Voltage & Frequency**
- 230/460V-60Hz (460V only ≥ 40 hp)
 - 575V-60Hz
 - 208V-60Hz
 - 400V-50Hz
 - 115/230V-60Hz, 1 ph.
 - Other _____

- Terminal Box Pos.**
- TB1
 - TB2
 - TB3
 - TB4

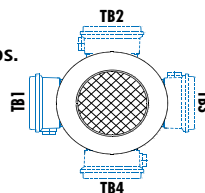

Mtg. Pos. M1 Shown

- Conduit Entry Loc.**
- CE I *
 - CE II
 - CE III *
 - CE IV

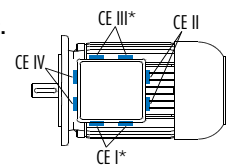

Mtg. Pos. M1 Shown

* Brakemotor